



T493 Series - KEMET Military COTS
Product Specification – 10-2-06

Component Outline Drawing

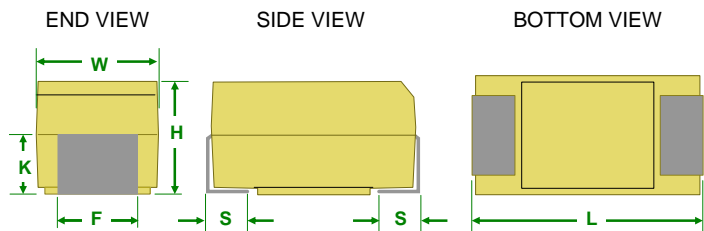

Component Marking

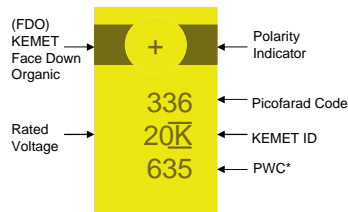

* 635 = 35th week of 2006

Case Codes		Component Dimensions					
		L	W	H	K Min	F ± 0.1	S ± 0.3
KEMET	EIA						
A	3216-18	3.2±0.2	1.6±0.2	1.6±0.2	0.7	1.2	0.8
B	3528-21	3.5±0.2	2.8±0.2	1.9±0.2	0.9	2.2	0.8
C	6032-28	6.0±0.3	3.2±0.3	2.5±0.3	1.2	2.2	1.3
D	7343-31	7.3±0.3	4.3±0.3	2.8±0.3	1.3	2.4	1.3
X	7343-43	7.3±0.3	4.3±0.3	4.0±0.3	2.1	2.4	1.3

Part Number and Electrical Specification Table

KEMET Part Number	Case	Cap	Voltage	DCL V _R	DF 120Hz	Std ESR, 100kHz mΩ	Low ESR, 100kHz mΩ	Ultra Low ESR, 100kHz mΩ
T493D157(1)016A(2)	D/4373-31	150 μF	16 V	24 μA	8 %	700	400	150

(1) To complete KEMET part number, insert "K" for +/- 10% or "M" for +/- 20% capacitance tolerance

(2) To complete KEMET part number, insert lead material designator "T" for 100% tin (Sn) termination or "H" for tin/lead (Sn/Pb) termination